

Air Conditioner Replacement Cords

3-Conductor Grounded • Type SPT-3 • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			PLUG CONFIG.	NEMA CONFIG.	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS						
04194.60.17	3	14	3	Beige	125	15	1875	Straight	5-15P	24	0.3	8	079407041947
04195.60.17	3	14	6	Beige	125	15	1875	Straight	5-15P	24	0.6	15	079407041657
04199.60.17	3	12	6	Beige	250	20	5000	Right Angle	6-20P	24	0.9	22	079407041992



Product Construction:

Conductor:

- 12 AWG and 14 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded PVC

Jacket:

- PVC; beige

Applications:

- For replacement use with air conditioners

Features:

- Conductor stripped 5/8"
- Free end slit 1 1/2"

Industry Approvals:

- UL Listed

Coiled Power Tool Extension Cords and Power Supply Cords

2 and 3 Conductor • Type SJT • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS					
06014.60.04	3	16	10	Orange	125	13	1625	5-15P/5-15R	10	1.1	11	079407060146
02551.70.01	3	16	12	Black	125	15	1875	5-15P	10	1.1	11	079407025510

Product Construction:

Conductor:

- 16 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded PVC

Jacket:

- PVC; orange or black
- Voltage rating: 300 volts

Applications:

- Workshop and tool bench use

Features:

- Coiled cord expands from 3' to 10' or 12'
- Right-angle plug helps prevent the cord from being pulled from the socket

Features (cont'd.):

- 06014.60.04 and 02551.70.01 are 3-conductor grounded

Industry Approvals:

- UL Listed
- OSHA Acceptable



Dryer Cords

Type SRDT • 30 Amps • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS					
05654.63.10	3	3#10	4	Gray	250	30	7500	10-30P	12	1.2	14	079407056545
05656.63.10	3	3#10	6	Gray	250	30	7500	10-30P	12	1.5	18	079407056569
01004.63.01	4	4#10	4	Black	250	30	7500	14-30P	12	1.5	18	079407010042
01006.63.01	4	4#10	6	Black	250	30	7500	14-30P	6	2.1	12	079407010066

Product Construction:

Conductor:

- 10 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded PVC

Jacket:

- PVC; black or gray

Applications:

- Dryers in homes built prior to 1997 (3-conductor)
- Dryers in homes built after 1997 (4-conductor)

Features:

- Right-angle cap
- Eyelet ends for safer hookups

Features (cont'd):

- Strain-relief clamp protects cord from damage caused by pulling or stretching

Industry Approvals:

- UL Listed
- Meets revised 1997 NEC requirements



Major Appliance Cords

3-Conductor Grounded • Type SPT-3 • 15 and 20 Amps • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS					
00436.63.17	3	14	6	Beige	125	15	1875	5-15P/5-15R	24	0.6	15	079407004362
00439.63.17	3	14	9	Beige	125	15	1875	5-15P/5-15R	24	0.9	21	079407004393
00442.63.17	3	14	12	Beige	125	15	1875	5-15P/5-15R	12	1.2	14	079407004423
00762.63.17	3	12	9	Beige	250	20	5000	6-20P/6-20R	24	1.4	34	079407007622
00772.63.17	3	12	9	Beige	125	20	2500	5-20P/5-20R	24	1.4	34	079407007721



Product Construction:

Conductor:

- 12 and 14 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade PVC; beige

Applications:

- Air conditioners
- Refrigerators
- Freezers
- Microwaves
- Dehumidifiers

Features:

- Molded right-angle plug

Industry Approvals:

- UL Listed

Pro Flex® Rubber Extension Cords

3-Conductor Grounded • Type SJ • 60°C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS					
06610.63.01	3	16	10	Black	125	13	1625	5-15P/5-15R	24	0.7	17	079407066100
06625.63.01	3	16	25	Black	125	13	1625	5-15P/5-15R	24	1.7	40	079407066254
06911.63.01	3	14	25	Black	125	15	1875	5-15P/5-15R	12	2.3	14	079407069118



Product Construction:

Conductor:

- 16 AWG through 14 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded EPDM

Jacket:

- CPE; black
- Temperature: 60°C
- Voltage rating: 300 volts

Applications:

- Floor polishers
- Sanders

Features:

- General use indoor cord
- 3-conductor grounded

Industry Approvals:

- UL Listed
- OSHA Acceptable for indoor use

Range Cords

Type SRDT • 50 Amps • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS					
05604.63.10	3	2#6 & 1#8	4	Gray	250	50	12500	10-50P	12	1.8	22	079407056040
05606.63.10	3	2#6 & 1#8	6	Gray	250	50	12500	10-50P	12	2.6	31	079407056064
00604.63.01	4	2#6 & 2#8	4	Black	250	50	12500	14-50P	12	2.2	27	079407006045
00606.63.01	4	2#6 & 2#8	6	Black	250	50	12500	14-50P	6	3.2	19	079407006069

Product Construction:

Conductor:

- 8 AWG through 6 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade PVC; black or gray

Applications:

- Ranges in homes built prior to 1997 (3-conductor)
- Ranges in homes built after 1997 (4-conductor)

Features:

- Right-angle cap
- Eyelet ends for safer hookups
- Strain-relief clamp protects cord from damage caused by pulling or stretching

Industry Approvals:

- UL Listed



Power Supply Replacement Cords

3-Conductor Grounded • Types SJ, SJOW and SJOOW • 60° C • 300 Volts



CATALOG NUMBER	CORD TYPE	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PLUG CONFIG.	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS						
02685.70.01	SJOOW	3	18	8	Black	125	10	1250	5-15P	Straight	25	0.6	14	079407026852
02686.70.01	SJOW	3	16	8	Black	125	13	1625	5-15P	Straight	35	0.7	24	079407026869
04932.70.01	SJ	3	16	12	Black	125	13	1625	5-15P	Straight	50	0.8	40	079407049325
04929.70.01	SJ	3	16	9	Black	125	13	1625	5-15P	Straight	50	0.6	30	079407049295
04926.70.01	SJ	3	16	6	Black	125	13	1625	5-15P	Straight	50	0.6	28	079407049264

Product Construction:

Conductor:

- 18 AWG or 16 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded EPDM

Jacket:

- CPE; black

Applications:

- For replacement use

Features:

- For replacement use
- Straight plug

Industry Approvals:

- UL Listed
- CSA

Power Supply Replacement Cords

2 and 3 Conductor • Types SJT and ST • 60° C • 300 Volts and 600 Volts



CATALOG NUMBER	CORD TYPE	NO. OF COND.	AWG OF SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PLUG CONFIG.	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS						

300 Volt

02523.73.01	SJT	3	18	3	Black	125	10	1250	5-15P	Straight	50	0.2	12	079407025237
01364.70.01	SJT	3	18	8'2"	Black	125	10	1250	5-15P	Straight	50	0.5	25	079407213641
02524.73.01	SJT	3	16	3	Black	125	13	1625	5-15P	Straight	50	0.3	14	079407025244
02547.70.01	SJT	3	16	6	Black	125	13	1625	5-15P	Straight	25	0.5	13	079407018444
01513.70.01	SJT	3	16	8'2"	Black	125	13	1625	5-15P	Straight	45	0.7	32	079407315130
04949.60.10	SJT	3	16	9	Gray	125	13	1625	5-15P	Straight	50	0.7	35	079407049493
01614.70.01	SJT	3	16	12	Black	125	13	1625	5-15P	Straight	50	0.9	44	079407016143
01278.70.01	SJT	2	16	8	Black	125	13	1625	1-15P	Straight	30	0.5	14	079407012787
01950.70.01	SJT	3	14	8	Black	125	15	1875	5-15P	Straight	50	0.8	41	079407019502

600 Volt

01951.70.01	ST	3	12	8	Black	125	15	1875	5-15P	Straight	25	1.8	45	079407719518
-------------	----	---	----	---	-------	-----	----	------	-------	----------	----	-----	----	--------------

With Switch	CORD TYPE	NO. OF COND.	AWG OF SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PLUG CONFIG.	SWITCH SPEED	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS							
01732.70.01	SJT	3	18	8	Black	125	10	1250	5-15P	Straight	1 Speed (On/Off)	25	0.7	18	079407017324
02053.70.01	SJT	3	18	12	Black	125	10	1250	5-15P	Straight	1 Speed (On/Off)	15	0.8	12	079407020539

With Strain Relief	CORD TYPE	NO. OF COND.	AWG OF SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PLUG CONFIG.	STRAIN RELIEF	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS							
02548.70.01	SJT	3	16	6	Black	125	13	1625	5-15P	Straight	7" From Free End	25	0.5	13	079407025480

With Receptacle Only	CORD TYPE	NO. OF COND.	AWG OF SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	RECEPTACLE CONFIG.	PKG. PER CTN.	WT./UNIT LBS	WT./CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS						
04530.73.01	SJT	3	16	3	Black	125	13	1625	5-15R	Straight	50	0.2	9	079407045303

Product Construction:

Conductor:

- 18 AWG through 12 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded PVC

Jacket:

- PVC; black or gray

Applications:

- For replacement use

Features:

- Straight plug
- Conductor stripped 5/8"
- Jacket removed 11/2"


Industry Approvals:

- UL Listed
- CSA

Power Supply Replacement Cords

3-Conductor Grounded • Types SPT-1 and SPT-3 • 60 °C • 300 Volts

CATALOG NUMBER	CORD TYPE	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	PLUG CONFIG.	PKG. PER CTN.	WT. / UNIT LBS	WT. / CTN. LBS	UPC CODE
						VOLTS	AMPS	WATTS						
02050.70.10	SPT-1	3	18	8	Gray	125	10	1250	5-15P	Straight	50	0.4	21	079407020508
02522.73.01	SPT-3	3	16	6	Black	125	13	1625	5-15P	Straight	25	0.6	14	079407025220
04106.73.10	SPT-3	3	16	6	Gray	125	13	1625	5-15P	Right Angle	50	0.4	22	079407041060
04103.73.10	SPT-3	3	16	3	Gray	125	13	1625	5-15P	Right Angle	100	0.3	26	079407041039
04806.73.10	SPT-3	3	16	6	Gray	125	13	1625	5-15P	Straight	50	0.4	19	079407048069
04803.73.10	SPT-3	3	16	3	Gray	125	13	1625	5-15P	Straight	100	0.3	27	079407048038

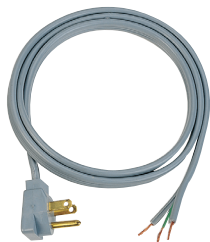

Product Construction:

Conductor:

- 18 AWG and 16 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade, color-coded PVC

Jacket:

- PVC; black, gray or beige

Applications:

- For replacement use

Features:

- Conductor stripped 5/8"
- Free end slit 1 1/2"

Industry Approvals:

- UL Listed

Power Supply Replacement Cords with Switch

3-Conductor Grounded • Type SJT • 60° C • 300 Volts

CATALOG NUMBER	NO. OF COND.	AWG SIZE	LENGTH OF CORD (FT)	COLOR OF JACKET	POWER RATING			NEMA CONFIG.	SWITCH SPEED	PKG. PER CTN.	WT./ UNIT LBS	WT./ CTN. LBS	UPC CODE
					VOLTS	AMPS	WATTS						
02336.70.01	3	16	10	Black	125	13	1650	5-15P	1 Speed (On/Off)	25	0.9	22	07940743242

Product Construction:

Conductor:

- 16 AWG stranded bare copper per ASTM B174

Insulation:

- Premium-grade,color-codedPVC

Jacket:

- PVC; black

Applications:

- For replacement use
- For fan replacements

Features:

- Switch
- Straight plug
- Conductor stripped 5/8"
- Jacket removed 2"

Industry Approvals:

- UL Listed
- CSA

