


# Irrigation & Landscape Lighting

## SOLUTIONS GUIDE

### Underground Feeder (UF) Cable 600 V Single Conductor, PVC Insulated

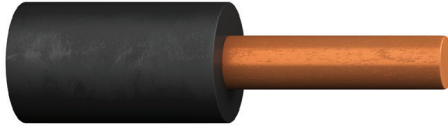

**Applications:**

- For use in irrigation as described in Article 339 of the National Electric Code (NEC)
- 18 AWG and 16 AWG are not permitted to be UL Listed as Type UF\*

**Standard Put-Ups:**

- 500'
- 1000'
- 2500'

**Standard Colors:**

- Please consult customer service for information on available colors

ISOTEC PART NUMBER	AWG/STRANDING	INSULATION THICKNESS INCHES	NOMINAL O.D. INCHES	WEIGHT PER MFT
<b>181UF*</b>	18 (Solid)	0.045	0.134	13
<b>161UF*</b>	16 (Solid)	0.045	0.144	17
<b>141UF</b>	14 (Solid)	0.060	0.186	28
<b>121UF</b>	12 (Solid)	0.060	0.205	37
<b>101UF</b>	10 (Solid)	0.060	0.225	52

Note: PE UF cable is available upon special request. Please consult customer service.